 



Common Mode Choke

TCK-194


| | |
|---------------------------|--|
| Order Code | TCK-194 |
| Inductance (each winding) | 180 µH ±35% (at 100 kHz / 100 mV) |
| Impedance (DCR) | 5 mΩ max. |
| Rated Current | 16 A max. |
| Operating Temperature | -40°C to +105°C |
| RoHS Exemptions | No Exemptions |
| Overview Link | www.tracopower.com/overview/tck-194 |



Impedance Curve

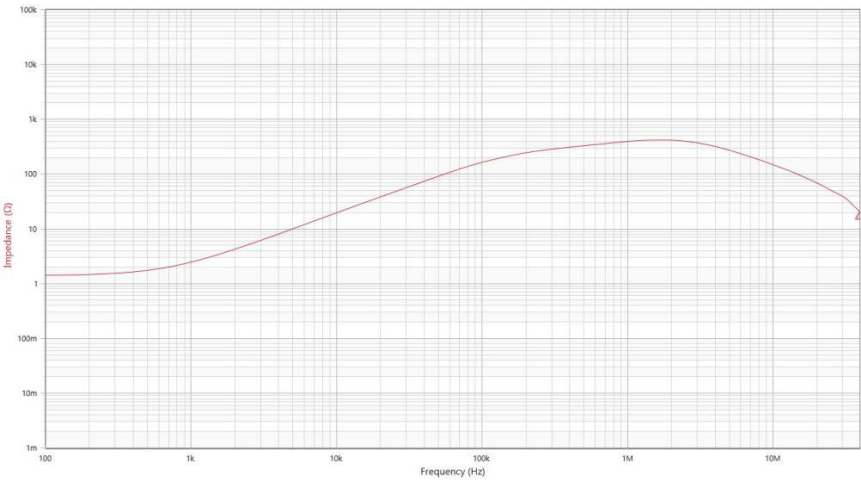

Outline Dimensions

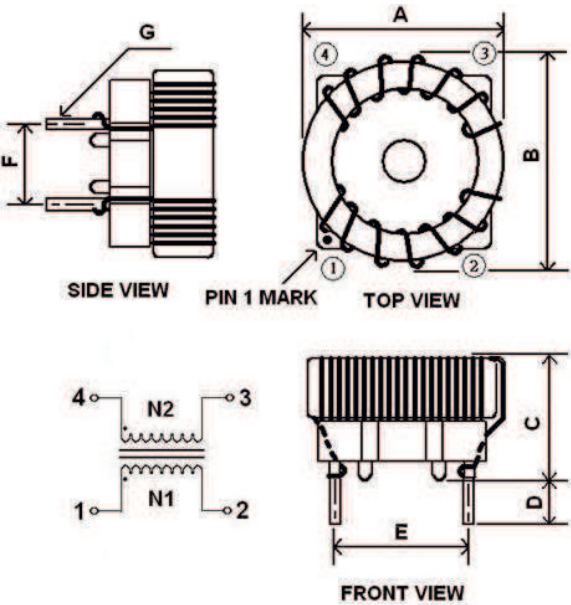

| Dimensions [mm] | |
|-----------------|-----------|
| A | 16.0 max. |
| B | 18.0 max. |
| C | 16.5 max. |
| D | 3.6 ±0.4 |
| E | 10.0 ±0.3 |
| F | 7.4 ±0.3 |
| G | Ø0.8 ±0.1 |

All specifications valid at +25°C, unless otherwise stated.